


**DIN 934** similar to ISO 4032

## Hexagon nuts

External hex

Plastic Natural polyamide | Cr(VI)-free | Metric thread

Further information: DIN-standard has been withdrawn | changed spanner widths for M10, M12, M14 and M22 | the fine thread has been transferred to ISO 8673

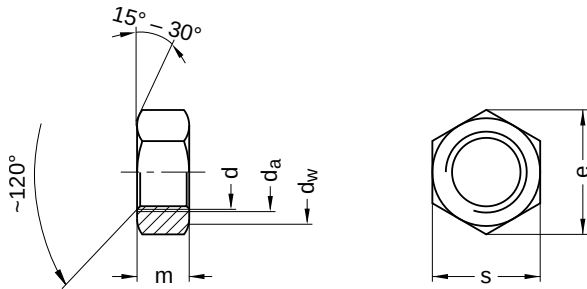

Diameter (d)	d <sub>a</sub>		d <sub>w</sub> min.	e min.	m		s		Pitch (P)
	min.	max.			min.	max.	min.	max.	
M 3	3	3.45	4.5	6.01	2.15	2.4	5.32	5.5	0.50
M 4	4	4.60	5.8	7.66	2.90	3.2	6.78	7.0	0.70
M 5	5	5.75	6.8	8.79	3.70	4.0	7.78	8.0	0.80
M 6	6	6.75	8.8	11.05	4.70	5.0	9.78	10.0	1.00
M 8	8	8.75	11.3	14.38	6.14	6.5	12.73	13.0	1.25
M 10	10	10.80	15.3	18.90	7.64	8.0	16.73	17.0	1.50
M 12	12	13.00	17.2	21.10	9.64	10.0	18.67	19.0	1.75
M 16	16	17.30	22.2	26.75	12.30	13.0	23.67	24.0	2.00

All technical data refer to the measure mm

