


DIN 934 similar to ISO 4032

Hexagon nuts

External hex

Steel 5 - 2 | hot-dip galvanised | Cr(VI)-free | Metric thread

Further information: DIN-standard has been withdrawn | changed spanner widths for M10, M12, M14 and M22 | the fine thread has been transferred to ISO 8673

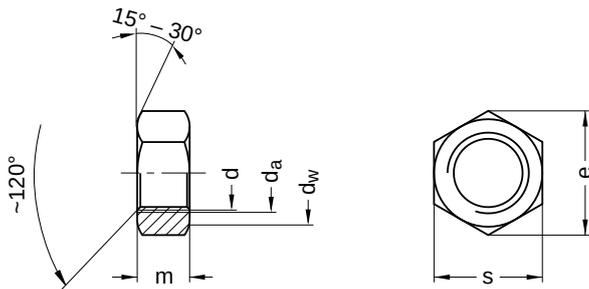

Diameter (d)	d _a		d _w	e	m		s		Pitch (P)
	min.	max.			min.	max.	min.	max.	
M 12	12	13.0	17.2	21.10	9.64	10	18.67	19	1.75
M 16	16	17.3	22.2	26.75	12.30	13	23.67	24	2.00
M 20	20	21.6	28.2	32.95	14.90	16	29.16	30	2.50
M 24	24	25.9	33.2	39.55	17.70	19	35.00	36	3.00

All technical data refer to the measure mm

