


Adapter coupling



Type	Valve	max. C
D-F100-CA	●	100
D-F100-CAT	—	100

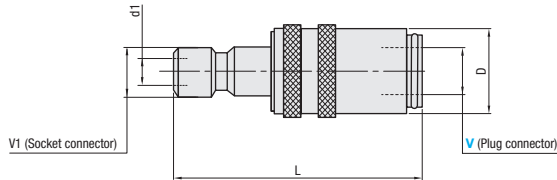

M C3604

D	L	d1	V1	Part No.	
				Type	V
17	41	6	9.4	D-F100-CA	9
22	52	9	13.5	D-F100-CAT	13



Order

Part No.
D-F100-CA9



Days to Ship



Stock



Price

Order / Quote:

WOS: <https://in.misumi-ec.com/>

TEL: +91-124-468-8800 E-mail: cs@misumi.co.in

Use in atmospheric pressure 2,500 Kpa (25.49 kgf/cm²) or lower.






Example

USA Type Couplings

Adapter Couplings

DIN Nipples

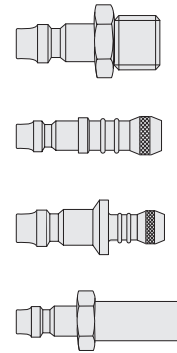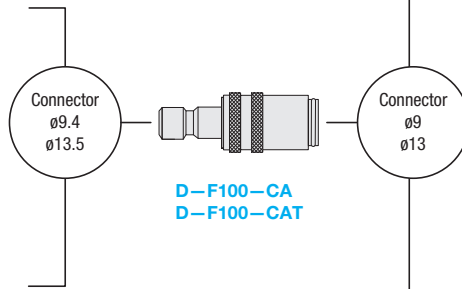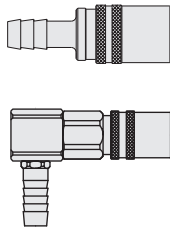


Misumi lineup:

- C-F120-MJTSH P.242
- C-F120-MJTSL P.242
- C-F120-MJTSHM P.242
- C-F120-MJTSLM P.242

Misumi lineup:

- D-NM P.236
- D-NMG P.236
- D-NMT P.236
- D-NMTG P.236
- D-NVT P.236
- D-NVTS P.236
- D-NLT P.236

JST8-5 (Sealing Tape) JST13-15

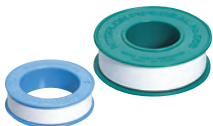

Fluorocarbon resin (PTFE)

Heat resistance temperature	W (width)	L (length) (meter)	t (thickness)	Part No.
260°C	8mm	5m	0.1mm	JST 8-5
	13mm	15m		JST13-15



Order

Part No.
JST8-5



Days to Ship



Stock



Price

 
Order / Quote:

WOS: <https://in.misumi-ec.com/>

TEL: +91-124-468-8800 E-mail: cs@misumi.co.in



Example



JST8-5 is narrow and prevents from cutting protrusion when winding around screw plugs and such.

