

DIN
TYPE

HOSE NIPPLES


— FEMALE THREAD TYPE / HOT WATER HOSES —

Use in atmospheric pressure 2,500 Kpa (25.49 kgf/cm²) or lower.

Female thread type



Type	Valve	max. °C	Thread
D-NPF	—	100	MxP
D-NPFG	—	100	PF(G)

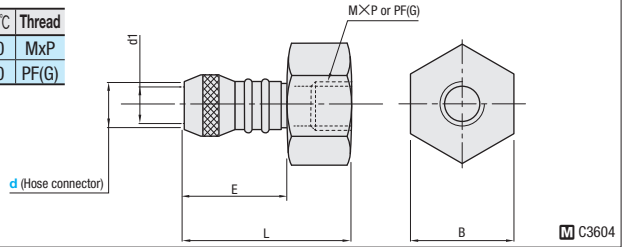

M C3604

Metric thread type

B	L	E	d1	M×P	Part No.		
					Type	d	M
17	40	23.5	6	M14×1.5	D-NPF	9	14
22	42	27	9	M16×1.5		13	16
30	52	32	13	M24×1.5		19	24

Parallel pipe thread type

B	L	E	d1	PF(G)	Part No.		
					Type	d	No.
17	40	23.5	6	G1/4	D-NPFG	9	2
22	42	27	9	G3/8		13	3
32	52	32	13	G3/4		19	6




Order

Part No.	—	M
D-NPF9	—	14
Part No.	—	No.
D-NPFG13	—	3



 Days to Ship



Stock



Price


Order / Quote:

WOS: <https://in.misumi-ec.com/>


TEL:+91-124-468-8800 E-mail:cs@misumi.co.in

Cooling
Components

Female thread type (Pusher lock type)

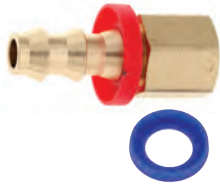

D-NPFL

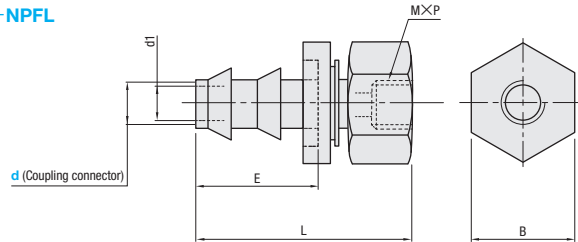

M C3604

A Rings (Red, Blue)

Usable temperature up to 100 °C

Metric thread type

B	L	E	d1	M×P	Part No.		
					Type	d	M
17	40	22.5	6	M14×1.5	D-NPFL	9	14
22	42	25	9	M16×1.5		13	16



Order

Part No.	—	M
D-NPFL13	—	16



Days to Ship



Stock



Price

Order / Quote:


WOS: <https://in.misumi-ec.com/>

TEL:+91-124-468-8800 E-mail:cs@misumi.co.in

Hot water hoses



D-MHW

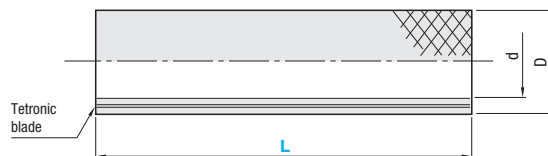

M PVC

D	Part No.		L
	Type	d	
15	D-MHW	9	10
17		13	
26		19	25

Specifications	Part No.		
	D-MHW9	D-MHW13	D-MHW19
Allowable pressure (MPa)	1.0	0.8	0.6
Allowable temperature range	0°C ~ 60°C		

The color may be different depending on the size.




Order

Part No.	—	L
D-MHW13	—	25



 Days to Ship



Stock



Price

Order / Quote:

WOS: <https://in.misumi-ec.com/>

TEL:+91-124-468-8800 E-mail:cs@misumi.co.in