

Ball Casters- screwable, plain bearing

22752.0124



Product Description

For positioning and aligning of workpieces.
Because of the slide bearing, the ball can roll permanently, and the surface of the workpiece is protected.

At temperatures > 20°C, the carrying figure decreases linearly. (Example: at 90°C the load bearing capacity is max. 60%)

Material

Bearing

- plastic

Ball

- Ball-bearing steel, hardened

Screw


- Free cutting steel, blackened

More information

Notes

Special types on request.

Drawing

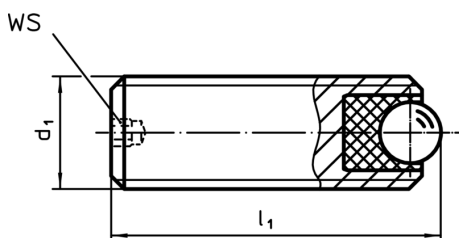

Order information

Dimensions			WS	Load capacity for static load max.	Tightening torque max.	Temperature		Weight	Art. No.
d ₁	l ₁ [mm]	Ball				min.	max.		
Free cutting steel									
M12	35	6,5	2,5	1161	1,44	-50	90	27	22752.0124

Application example

